


Water Resistant Handheld Thermocouple Meters

HH601A Series
Starts at
£101



- ✓ Water Resistant Housing
- ✓ °C/°F Switchable
- ✓ Display Hold
- ✓ Continuously Displays High/Low Values
- ✓ Long Battery Life
- ✓ High Accuracy
- ✓ Wide Temperature Range
- ✓ 0.1° Resolution Up to 999.9°C or °F (HH602A, HH603A)
- ✓ Low Battery Warning
- ✓ Automatic Shut-Off Timer

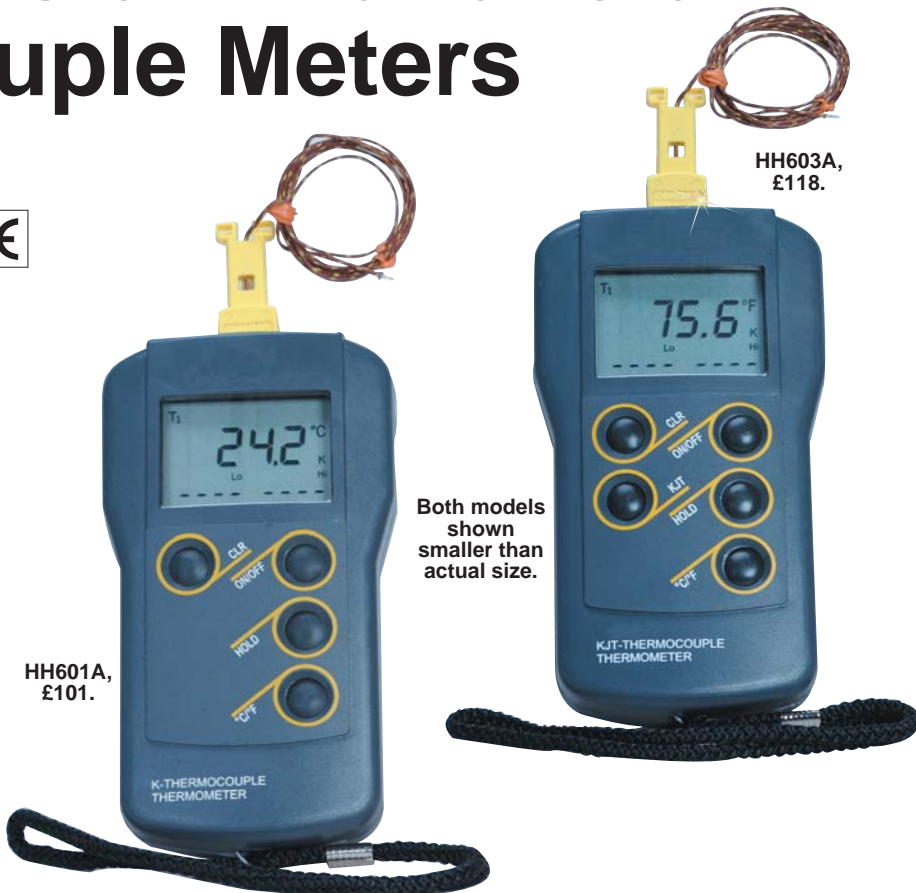

HH601A, £101.

HH603A, £118.

The HH600A Series units are water resistant, very accurate handheld thermocouple meters. The HH601A is a low-cost unit with a Type K input that has 0.1° resolution to 199.9°C and automatically switches to 1° resolution for higher temperatures. The HH602A is a higher accuracy Type K unit with 0.1° resolution to 999.9°C or °F. The HH603A is the same as the HH602A, but can be used for J or T thermocouples as well as Type K. All the units feature a dual LCD displays which continuously display the high and low readings as well as the current temperature.

HH602A and HH603A:
0.1°C from -149.9 to 999.9°C,
0.2°C from -200.0 to -150.0°C,
1°C from 1000 to 1371°C;
0.1°F from -24.9 to 999.9°F,
0.2°F from -249.9 to 25.0°F,
0.3°F from -328.0 to 250.0°F,
1°F from 1000 to 2500°F

Accuracy (At Ambient, Excluding Probe):
HH601A: ±0.2% FS
HH602A and HH603A: ±0.5°C (-100.0 to 999.9°C), ±1°C outside; ±1°F (-148.0 to 999.9°F), ±1.5°F outside

Battery Life:
HH601A: 1600 hours continuous
HH602A and HH603A: 500 hours continuous
Battery Type: Three 1.5 V "AA" (included)
Auto Off Select:
HH601A: 8-min, 60-min or off
HH602A and HH603A: 60-min or off
Weight:
HH601A: 235 g (8.3 oz)
HH602A and HH603A: 250 g (8.8 oz)
Dimensions: 150 x 80 x 36 mm (5.9 x 3.1 x 1.4")
Connection: Mini (flat-pin) socket

Specifications

Input Type:

HH601A and HH602A: Type K
HH603A: Types K, J, or T

Range:

HH601A: -50 to 1350°C (-58 to 2462°F)

HH602A: -200 to 1371°C (-328 to 2500°F)

HH603A:

K: -200 to 1371°C (-328 to 2500°F)

J: -200 to 999°C (-328 to 1832°F)

T: -200 to 400°C (-328 to 752°F)

Resolution:

HH601A: 0.1°C from 50.0 to 199.9°C, 1°C from 200 to 1350°C;

0.1°F from -58.0 to 399.9°F,

1°F from 400 to 2462°F

ALL MODELS AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)		
Model No.	Price	Description
HH601A	£101	Type K handheld autoranging thermometer
HH602A	107	Type K handheld high accuracy thermometer
HH603A	118	Type J, K or T handheld high accuracy thermometer
Accessories		
CAL-3-HH	50	Traceable calibration certificate with results
HH600A-SC	8	Soft carrying case

Comes with batteries, beaded Type K T/C, wrist-strap, and operator's manual.

All meters accept mini plugs. (OMEGA SMPW type).

Ordering Example: HH601A, Type K input handheld, water-resistant thermometer with min/max/display hold functions, £101.



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters