

# Economical Handheld Thermometer

## With Magnet Hanger

**POCKET PAL®**

HH74K  
\$55




No Points

- ✓ Lightweight Design
- ✓ Pocket Hook and Magnet Hanger
- ✓ ADJ Thermocouple Offset Function
- ✓ Max/Data Hold Function
- ✓ Auto Power-Off Function Can be Disabled
- ✓ Battery Life 300 Hours Typical Use
- ✓ °C or °F Switchable
- ✓ NIST-Traceable Certificate of Calibration (No Points)



HH74K, \$55, shown with optional SA1-K-SC, self-adhesive thermocouple, \$75 for package of 5. Search [omega.com](http://omega.com)

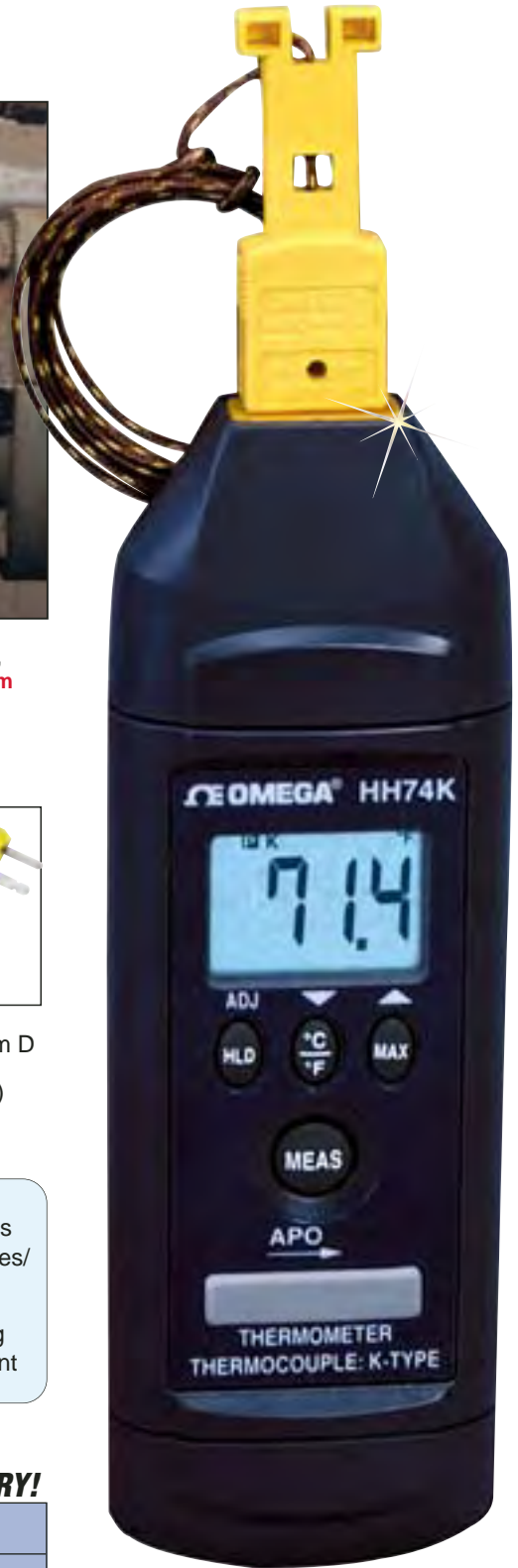

HH74K, \$55, shown smaller than actual size.

### Specifications

**Display:** 3½ digit LCD

**Low-Battery Indication:**

The "BL" is displayed

**Measurement Rate:** 2.5 times per second

**Operating Environment:** 0 to 50°C (32 to 122°F) @ <70% RH

**Storage Environment:** -20 to 60°C (-4 to 140°F), 0 to 80% RH with battery removed from meter

**Stated Accuracy:**

23 ±5°C (73 ± 9°F), <75% RH

**Battery:** Three 1.5 V "AAA" (included)

**Battery Life:** 300 hours, typical use

**Temperature:**

**Range:** -100 to 850°C (-148 to 1562°F)

Type K (CHROMEGA®-ALOMEGA®)

**Resolution:** 1°C or 1°F, 0.1°C or 0.1°F

**Accuracy (Does Not Include Probe):**

18 to 28°C (64 to 82°F) ambient

±(0.3% rdg + 1°C) on °C ranges

±(0.3% rdg + 2°F) on °F ranges

**Resolution**

**Range**

0.1°C -59.9 to 199.9°C

1°C -100 to -60°C

200 to 850°C

0.1°F -59.9 to 199.9°F

1°F -148 to -60°F

200 to 1562°F

### Thermocouple Included!

HH74K models include a free 1 m (40") Type K insulated beaded wire thermocouple with subminiature connector and wire spool caddy (1 per channel). **Order a Spare! Model No. SC-GG-K-30-36, \$15.**

**Dimensions:** 148 H x 48 W x 24 mm D (5.8 x 1.9 x .94")

**Weight:** Approximately 74 g (2.6 oz) with battery

**Connector:** SMP

### Applications

- ✓ Greenhouses
- ✓ Office Environment
- ✓ Environmental Studies
- ✓ Labs
- ✓ Workshops
- ✓ Art Galleries/Museums
- ✓ Weather Monitoring
- ✓ Department Stores

**AVAILABLE FOR FAST DELIVERY!**

### To Order (Specify Model Number)

Model No.	Price	Description
HH74K	\$55	Type K thermometer
SC74	10	Soft carrying case

Comes with operator's manual, thermocouple, magnet hanger, NIST certificate and batteries.

**Ordering Example:** HH74K, Type K thermometer with magnet hanger, \$55.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters