




Moulded M8 and M12 Thermocouple Extension Cable

M8C and M12C Series
Starts at
£7.40

- ✓ Available in M8 and M12 Constructions
- ✓ Female Connectors Attach to Male (Pin) Sensor Connectors
- ✓ M12 Cables Have Thermocouple Compensated Wires
- ✓ Wires Have Silicone Insulation and Jacket

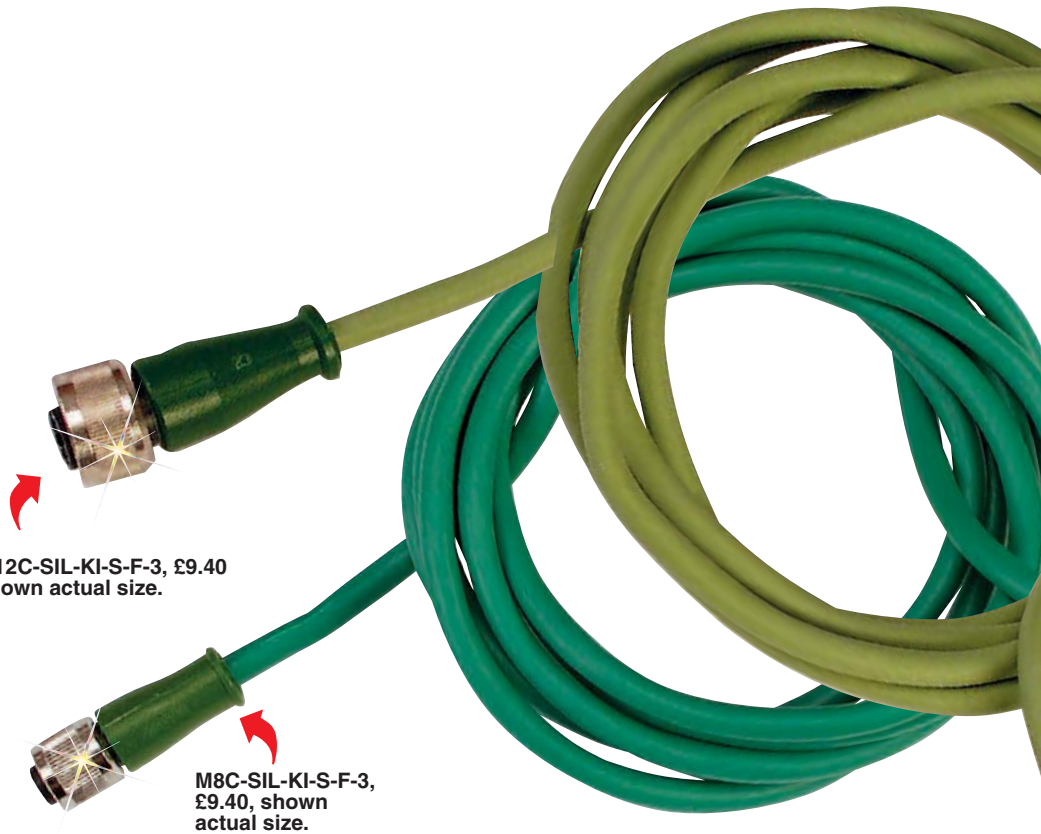

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)				
Model Number	Price	Thermocouple Type	Cable Length	Connector Orientation
M12 Extension Cables				
M12C-SIL-JI-S-F-1.5	£7.40	J	1.5 m	Straight
M12C-SIL-KI-S-F-1.5	7.40	K	1.5 m	Straight
M12C-SIL-JI-S-F-3	8.70	J	3.0 m	Straight
M12C-SIL-KI-S-F-3	9.40	K	3.0 m	Straight
M12C-SIL-KI-S-F-5	12	K	5.0 m	Straight
M8 Extension Cables				
M8C-SIL-JI-S-F-1.5	£7.40	J	1.5 m	Straight
M8C-SIL-KI-S-F-1.5	7.40	K	1.5 m	Straight
M8C-SIL-JI-S-F-3	8.70	J	3.0 m	Straight
M8C-SIL-KI-S-F-3	9.40	K	3.0 m	Straight
M8C-SIL-JI-S-F-5	10.75	K	5.0 m	Straight
M8C-SIL-KI-S-F-5	12	K	5.0 m	Straight

Ordering Examples: M12C-SIL-JI-S-F-3, thermocouple extension cable, Type J silicone insulated and jacketed cable, 3 m long with straight M12 female connector one end, £8.

M8C-SIL-KI-S-F-5, thermocouple extension cable, Type K silicone insulated and jacketed cable, 1.5 m long with straight M8 female connector one end, £12.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters