


# Non-Reversible OMEGALABEL® Temperature Monitors

**MOST POPULAR MODELS HIGHLIGHTED!**

## Button Series

4 temperature ratings on each label.  
Temperatures are read clockwise starting at the "V" mark:

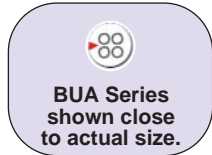

8 mm (0.3") **Outside Diameter**  
1.2 mm (0.05") **Indicating Window**

To order package of 30,  
add suffix "-30" to model number.  
**Ordering Example: BUA-100/38-30,**  
button series label 38 to 54°C  
(100 to 130°F), package of 30, **£37.**

**Price**  
pkg of 10    pkg of 30  
**£13<sup>50</sup>**    **£37**

## Specifications

**Accuracy:** Up to 99°C (210°F) is ±1°C (1.8°F); From 100°C (212°F) to 154°C (309°F) is ±1.5°C (2.7°F); From 160°C (320°F) to 280°C (536°F) is ±1% and ±1°C (1.8°F)

Model No. (Pkg 10)	Temperature Ratings				
BUA-100/38	°C	38	43	49	54
	°F	100	110	120	130
BUA-120/49	°C	49	54	60	66
	°F	120	130	140	150
BUA-140/60	°C	60	66	71	77
	°F	140	150	160	170
BUA-160/71	°C	71	77	82	88
	°F	160	170	180	190
BUA-180/82	°C	82	88	93	99
	°F	180	190	220	210
BUA-175/79	°C	79	93	107	121
	°F	175	200	225	250
BUA-225/107	°C	107	121	135	149
	°F	225	250	275	300

## Series 6M

6 temperature ratings on each label:

**6MA** - 5.6°C (10°F) between each rating  
**6MB** - 13.9°C (25°F) between each rating  
32 x 10 mm (1.3 x 0.4") **Actual Size**  
0.4 x 3 mm (0.02 x 0.13") **Indicating Window**

To order package of 30,  
add suffix "-30" to model number.  
**Ordering Example: 6MA-130/54-30,**  
6 temperature rating 54 to 82°C  
(130 to 180°F), package of 30, **£36.**



Shown actual size.

**Price**  
pkg of 10    pkg of 30  
**£12**    **£36**

Model No. (Pkg 10)	Temperature Ratings						
6MA-100/38	°C	38	43	49	54	60	66
	°F	100	110	120	130	140	150
6MA-130/54	°C	54	60	66	71	77	82
	°F	130	140	150	160	170	180
6MA-160/71	°C	71	77	82	88	93	99
	°F	160	170	180	190	200	210
6MA-190/88	°C	88	93	99	104	110	116
	°F	190	200	210	220	230	240
6MA-220/104	°C	104	110	116	121	127	132
	°F	220	230	240	250	260	270
6MA-250/21	°C	121	127	132	138	143	149
	°F	250	260	270	280	290	300
6MB-100/38	°C	38	52	66	79	93	107
	°F	100	125	150	175	200	225
6MB-175/79	°C	79	93	107	121	135	149
	°F	175	200	225	250	275	300

## Series 8M

8 temperature ratings on each label:

**8MA** - 5.6°C (10°F) between each rating  
**8MB** - 13.9°C (25°F) between each rating  
42 x 10 mm (1.6 x 0.4") **Actual Size**  
0.4 x 3 mm (0.02 x 0.13") **Indicating Window**

To order package of 30, add suffix  
"-30" to Model No.

**Ordering Example: 8MA-180/82-30,** 8 temperature rating,  
82 to 121°C (180 to 250°F), package of 30, **£56.**



Shown actual size.

**Price**  
pkg of 10    pkg of 30  
**£18<sup>75</sup>**    **£56**

Model No. (Pkg 10)	Temperature Ratings								
8MA-100/38	°C	38	43	49	54	60	66	71	77
	°F	100	110	120	130	140	150	160	170
8MA-140/60	°C	60	66	71	77	82	88	93	99
	°F	140	150	160	170	180	190	200	210
8MA-180/82	°C	82	88	93	99	104	110	116	121
	°F	180	190	200	210	220	230	240	250
8MA-230/110	°C	110	116	121	127	132	138	143	149
	°F	230	240	250	260	270	280	290	300
8MB-100/38	°C	38	52	66	79	93	107	121	135
	°F	100	125	150	175	200	225	250	275


## ML4C Series Mini Labels

4 temperature ratings per label:  
12 x 5 mm (0.5 x 0.2") **Actual Size**  
1.5 mm (0.06") **Indicating Circle**

To order package of 30, add suffix  
"-30" to model number.

**Ordering Example: ML4C-40-30,**  
mini label, 4 temperature rating  
(40 to 49°C), package  
of 30, **£21.50.**


Actual size.

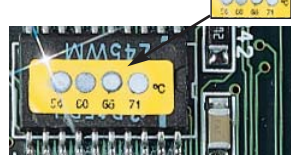

Shown larger than actual size for detail.

**Price**  
pkg of 10    pkg of 30  
**£8**    **£21<sup>50</sup>**

Model No. (Pkg 10)	Temperature Ratings				
ML4C-40	°C	40	43	46	49
ML4C-54	°C	54	60	66	71
ML4C-77	°C	77	82	88	93
ML4C-99	°C	99	104	110	116
ML4C-121	°C	121	127	132	138
ML4C-143	°C	143	149	154	160
ML4C-166	°C	166	171	177	182
ML4C-188	°C	188	193	199	204
ML4C-210	°C	210	216	224	232
ML4C-241	°C	241	249	254	260

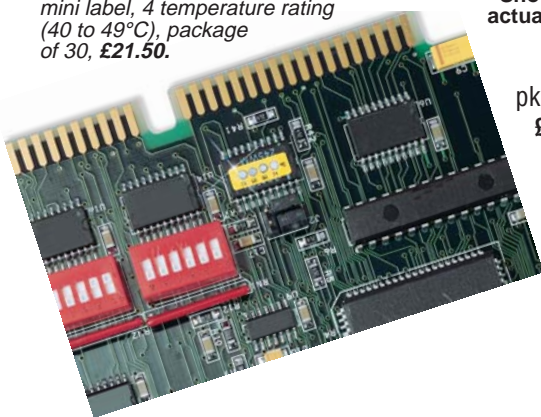



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA

Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)

1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenpfronn, Germany

0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England

0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)

088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)

Karviná, Czech Republic

596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters