

Precision Linear Thermistor Sensors

OL-701 and OL-702 Series


Starts at
\$47



General Purpose Sensors Shown Can Be Buried for Measuring Soil Temperatures or Used in a Variety of Applications


- ✓ Contain 2 Thermistor Sensors— Combined with Matching Resistor Sets They, Provide a Linear Response to Temperature (vs. the Non-Linear Response Provided By Most Thermistors)

- ✓ Sensors Provided with 3 m (10') of PVC Insulated Cable and Phone Plug Connector
- ✓ Temperature Range 0 to 100°C (32 to 212°F)
- ✓ Interchangeability $\pm 0.15^\circ\text{C}$

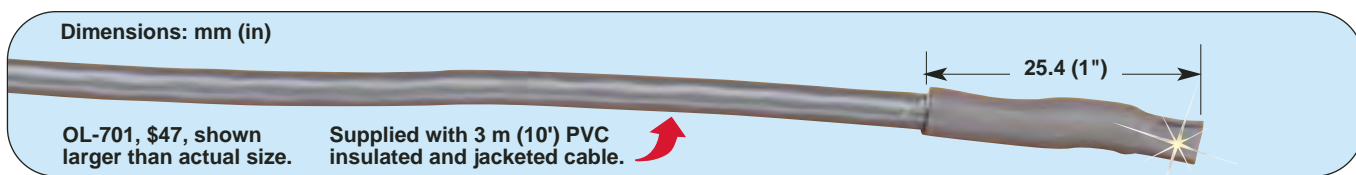


AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)						
Model No.	Price	Sensor Type	Thermistor Model Number	Resistance #1 @ 25°C	Resistance #2 @ 25°C	Termination
OL-701	\$47	Vinyl-sleeved tip	44018	6000Ω	30000Ω	Stripped leads
OL-701-PP	54	Vinyl-sleeved tip	44018	6000Ω	30000Ω	Phone plug

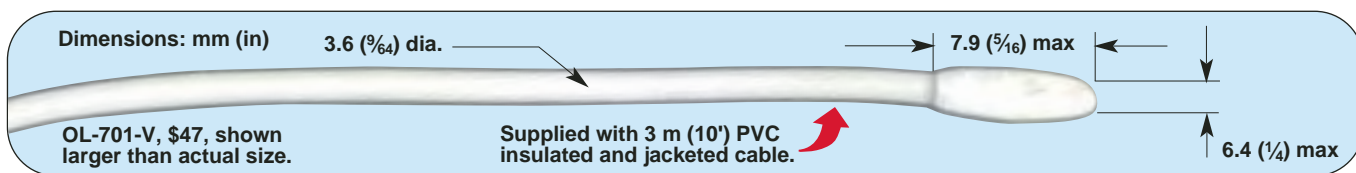

Model No.	Price	Sensor Type	Thermistor Model Number	Resistance #1 @ 25°C	Resistance #2 @ 25°C
OL-701-V	\$47	Vinyl tipped	44018	6000Ω	30000Ω

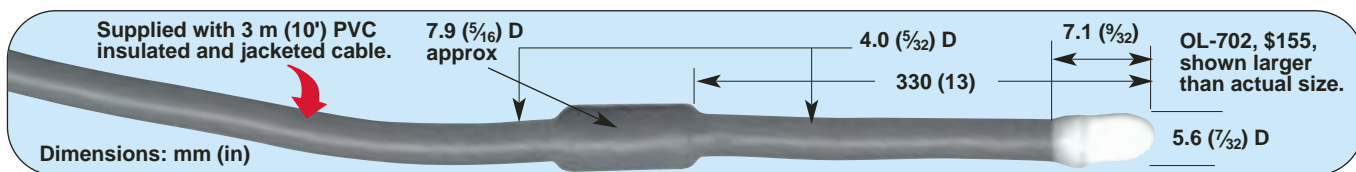

Model No.	Price	Sensor Type	Thermistor Model Number	Resistance #1 @ 25°C	Resistance #2 @ 25°C
OL-702	\$155	Vinyl tips	44018	6000Ω	30000Ω

Ordering Example: OL-701, vinyl sleeved tip sensor with 44018 thermistor and 3 m (10') of PVC insulated cable, \$47.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters