


Economical, High-Temperature Surface Probe




SPHT Series
Starts at
£30

- ✓ Ceramic Tip with Spring-Loaded Contacts Rated to 650°C
- ✓ J, K, or E Surface Probes Available
- ✓ 150 and 300 mm Long Surface Probes Available
- ✓ Moulded Utility Handle Rated to 220°C
- ✓ Retractable Cable Expands to 1.5 m
- ✓ Subminiature Connector for Use with Handheld Thermometers
- ✓ 304 SS OMEGACLAD™ Sheath

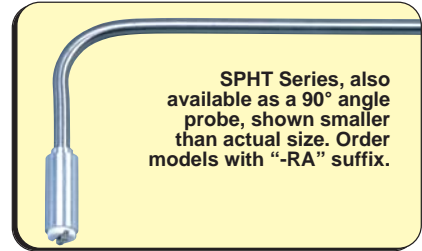

SPHT-K-6-IEC, retractable cable shown smaller than actual size.

Dimensions: mm

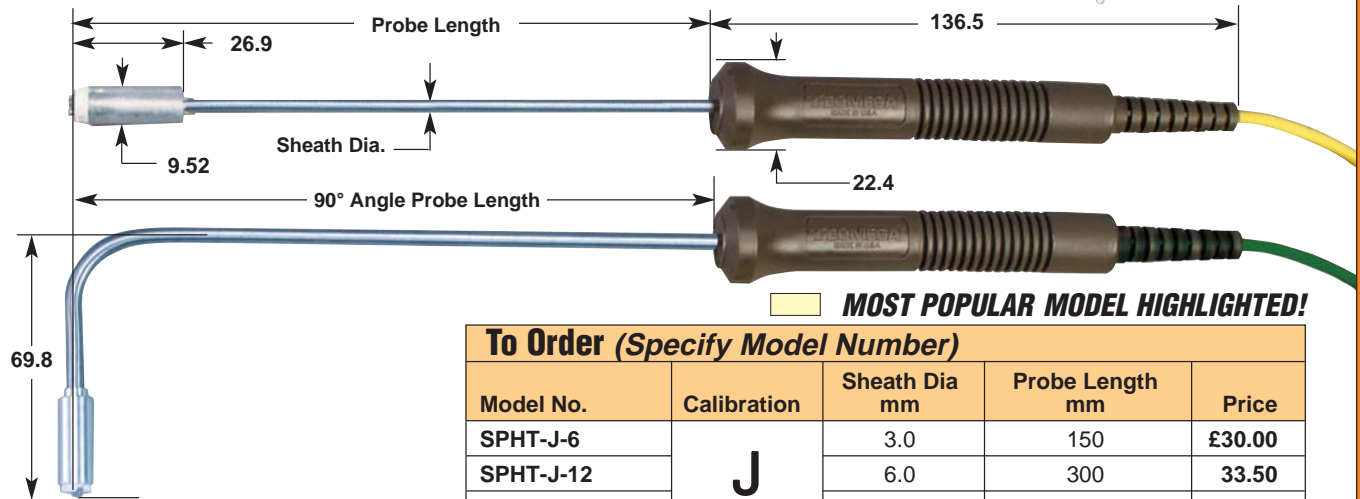

MOST POPULAR MODEL HIGHLIGHTED!

To Order (Specify Model Number)				
Model No.	Calibration	Sheath Dia mm	Probe Length mm	Price
SPHT-J-6	J	3.0	150	£30.00
SPHT-J-12		6.0	300	33.50
SPHT-J-12-RA		6.0	300	37.00
SPHT-K-6-IEC	K	3.0	150	30.00
SPHT-K-12-IEC		6.0	300	33.50
SPHT-K-12-RA-IEC		6.0	300	37.00
SPHT-E-6		3.0	150	30.00
SPHT-E-12		6.0	300	33.50
SPHT-E-12-RA		6.0	300	37.00

The SPHT-K-6 is included at No Additional Cost With These Infrared Thermometers

OS532E	OS532E-DM
OS533E	OS533E-DM
OS534E	OS534E-DM
OSXL689	OS534E-CF
	OS533E-CF

See pages 232 through 236 for information on these models

Comes with a plastic cap for protection of the surface element.
Ordering Examples: SPHT-K-12-IEC, 300 mm long, Type K surface probe, £33.50.
 SPHT-J-12-RA, 300 mm long, Type J, 90° right angle surface probe, £37.00.



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters