

# Non-Reversible OMEGALABEL® Temperature Labels TL-3, 4, and 5 Range Series

- ✓ Adhesive Backs for Easy Mounting.
- ✓ Indicator Turns Black When Exposed

### Applications:

- General • Aeronautical • Electrical • HVAC
- All applications where size is not a conditioning factor

**ALL MODELS AVAILABLE FOR FAST DELIVERY!**

### 3-Temperature Range Labels TL-3 SERIES 26 x 18 mm



Price  
pk of 10  
**£6<sup>70</sup>**  
pk of 30  
**£19<sup>50</sup>**

Model No.	Temperature Range
TL-3-105(*)	°F 105 110 115 °C 40 43 46
TL-3-120(*)	°F 120 130 140 °C 49 54 60
TL-3-150(*)	°F 150 160 170 °C 66 71 77
TL-3-180(*)	°F 180 190 200 °C 82 88 93
TL-3-210(*)	°F 210 220 230 °C 99 104 110
TL-3-240(*)	°F 240 250 260 °C 116 121 127
TL-3-270(*)	°F 270 280 290 °C 132 138 143
TL-3-300(*)	°F 300 310 320 °C 149 154 160
TL-3-330(*)	°F 330 340 350 °C 166 171 177
TL-3-360(*)	°F 360 370 380 °C 182 188 193
TL-3-390(*)	°F 390 400 410 °C 199 204 210
TL-3-420(*)	°F 420 435 450 °C 216 224 232
TL-3-465(*)	°F 465 480 490 °C 241 249 254

\*Insert "-10" for pack of 10 or "-30" for pack of 30.  
**Ordering Example: TL-3-210-30 Three Temperature Range Labels (210, 220, 230°F), pack of 30; £19.50**

### 4-Temperature Range Labels TL-4 SERIES 30 x 18 mm




Price  
pk of 10  
**£8**  
pk of 30  
**£23<sup>50</sup>**

Model No.	Temperature Range
TL-4-105(*)	°F 105 110 115 120 °C 40 43 46 49
TL-4-130(*)	°F 130 140 150 160 °C 54 60 66 71
TL-4-170(*)	°F 170 180 190 200 °C 77 82 88 93
TL-4-210(*)	°F 210 220 230 240 °C 99 104 110 116
TL-4-250(*)	°F 250 260 270 280 °C 121 127 132 138
TL-4-290(*)	°F 290 300 310 320 °C 143 149 154 160
TL-4-330(*)	°F 330 340 350 360 °C 166 171 177 182
TL-4-370(*)	°F 370 380 390 400 °C 188 193 199 204
TL-4-410(*)	°F 410 420 435 450 °C 210 216 224 232
TL-4-465(*)	°F 465 480 490 500 °C 241 249 254 260

\*Insert "-10" for pack of 10 or "-30" for pack of 30.  
**Ordering Example: TL-4-410-30 Four Range Temperature Labels (410, 420, 435, 450°F), pack of 30; £23.50**

### 5-Temperature Range Labels TL-5 SERIES 34 x 18 mm

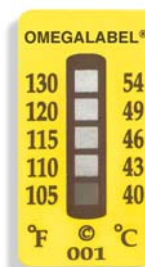

Price  
pk of 10  
**£7<sup>00</sup>**  
pk of 30  
**£19<sup>50</sup>**

Model No.	Temperature Range
TL-5-105(*)	°F 105 110 115 120 130 °C 40 43 46 49 54
TL-5-140(*)	°F 140 150 160 170 180 °C 60 66 71 77 82
TL-5-190(*)	°F 190 200 210 220 230 °C 88 93 99 104 110
TL-5-240(*)	°F 240 250 260 270 280 °C 116 121 127 132 138
TL-5-290(*)	°F 290 300 310 320 330 °C 143 149 154 160 166
TL-5-340(*)	°F 340 350 360 370 380 °C 171 177 182 188 193
TL-5-390(*)	°F 390 400 410 420 435 °C 199 204 210 216 224
TL-5-450(*)	°F 450 465 480 490 500 °C 232 241 249 254 260

\*Insert "-10" for pack of 10 or "-30" for pack of 30.  
**Ordering Example: TL-5-105-30 Five Range Temperature Labels (105, 110, 115, 120, 130°F), pack of 30; £19.50**

All models shown actual size.



Check pipe temperatures quickly and easily.



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA

Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)

1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenpfronn, Germany

0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England

0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)

088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)

Karviná, Czech Republic

596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters